



# Accuracy made easy

SlideMate AS Slide Printer




## How Does It Work?

- Data is sent from the LIS or scanned from the histology cassette to generate a barcode and slide identifier
- Templates can be customised
- Slides are printed using the intuitive software

## Slide Delivery System

- The optional Slide Delivery System is designed to hold 72 slides to reduce handling
- EpreDia SlideMate slides can be loaded using optimised packaging

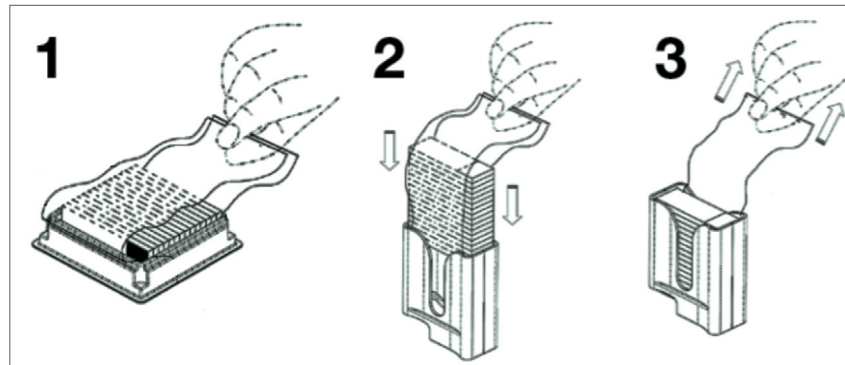

## Printing with SlideMate AS is easy as...



# SlideMate AS On-Demand Slide Printer

## Accurate Identification

- On-demand slide printing at the microtome can increase accuracy as patient identification is maintained

## Efficiency

- The SlideMate AS is designed to print slides within 5 seconds, enhancing workflow at the microtome

## Connectivity

- SlideMate AS has the option of being connected to other computers as well as LIS or LIMS using a Windows® driver

## Workflow Enhancement

- SlideMate AS may be used for barcoding slides within the workflow which allows for additional applications of automated archiving and digital pathology
- With its small footprint, the SlideMate AS slide printer fits directly next to your microtome

## The essential partner to your microtome



Fully automated HM355S rotary microtome

Optional slide hopper allows for quicker and easier on-demand printing of slides. Slides can automatically feed from the hopper.

Visit [www.epredia.com](http://www.epredia.com) to learn about SlideMate Pro dual hopper on-demand slide printer.



## SlideMate AS Printer Ordering Information

Systems	Order Number
<b>SlideMate AS Basic Printer</b> SlideMate AS basic printer with color touchscreen, power supply, power cord and Windows® Printer Driver software to print externally generated slide label from an image file	<b>A83900001</b>
<b>SlideMate AS Basic Printing System</b> SlideMate AS basic printer with slide delivery system, color touchscreen, power supply, power cord and Windows® Printer Driver software to print externally generated slide label from an image file	<b>A83900002</b>
<b>SlideMate AS On-Demand Printer</b> SlideMate AS on-demand printer with color touch-screen, built-in scanner, power supply, power cord and advanced software enabling label creation, special panel printing and import from LIS	<b>A83900004</b>
<b>SlideMate AS On-Demand Printing System</b> SlideMate AS on-demand printer with slide delivery system, color touch-screen, built-in scanner, power supply, power cord and advanced software enabling label creation, special panel printing and import from LIS	<b>A83900005</b>
Accessories	Cat. Number
Thermal transfer ribbon	A83910001
Slide delivery system	A83910002
Spare slide hopper for SlideMate AS slide delivery system	A83920016
Gateway software (1 unit)	A83910005
Multi-Gateway software (up to 10 units)	A83910009
Head cleaning kit	A83910008

## SlideMate AS Printer Specifications


Dimensions: SlideMate AS printer	
D x W X H	230 x 122 x 290 mm 9.1 x 4.8 x 11.5 in
Dimensions: SlideMate AS printer with slide delivery system and hopper	
D x W X H	230 x 122 x 470 mm 9.1 x 4.8 x 18.5 in
Printer Weight	4 kg, 9.5 lbs
Power requirements:	Universal 100 – 240 VAC, 50 – 60 Hz, 1.2A Max.
Slide type	25 mm x 75 mm x 1mm or 1 in x 3 in
Print speed	Up to 9 slides per minute with slide delivery system Up to 12 slides per minute with manual feed
Media type	Thermal transfer ribbon
Media capacity	1 roll, approximately 12,000 slides per roll
Media color	Black
Connectivity	Ethernet, USB-A (2), USB-B (1)

## SlideMate slides and SlideMatePLUS adhesion slides from EpreDia

Experience crisp, clean printing with SlideMate microscope slides from EpreDia, designed for the SlideMate AS slide printer.

SlideMate	Cat. Number
White	TT-40418217-W
Blue	TT-50418217-B
Green	TT-60418217-G
Pink	TT-70418217-P
Yellow	TT-80418217-Y

SlideMate PLUS	Cat. Number
White	TT-40418218-PS-W
Blue	TT-50418218-PS-B
Green	TT-60418218-PS-G
Pink	TT-70418218-PS-P
Yellow	TT-80418218-PS-Y

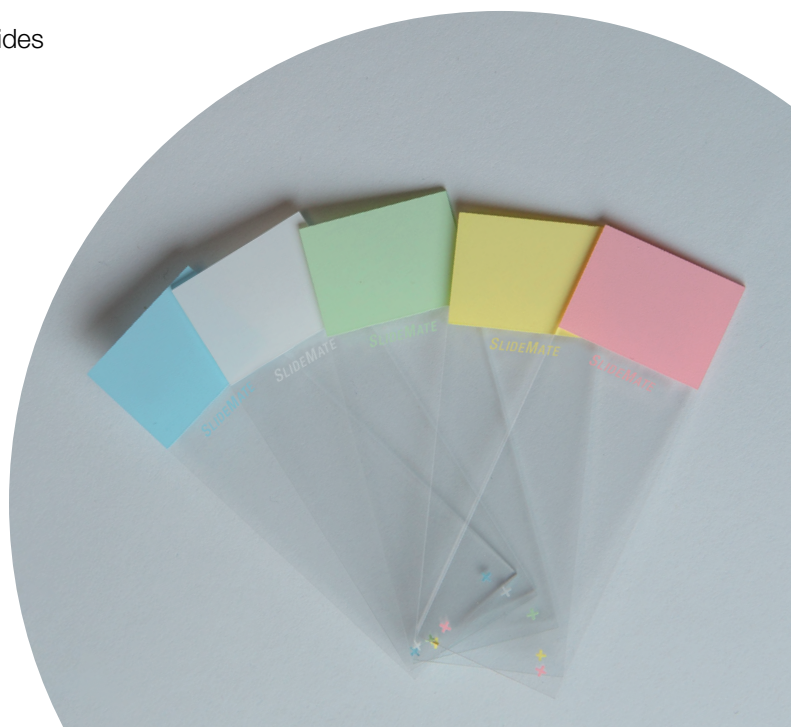

Distributed by Fisher Scientific. Contact us today:

Austria: fishersci.at Belgium: fishersci.be Denmark: fishersci.dk  
Germany: fishersci.de Ireland: fishersci.ie Italy: fishersci.it  
Finland: fishersci.fi France: fishersci.fr Netherlands: fishersci.nl  
Norway: fishersci.no Portugal: fishersci.pt Spain: fishersci.es  
Sweden: fishersci.se Switzerland: fishersci.ch UK: fishersci.co.uk

© 2023 Thermo Fisher Scientific Inc. All rights reserved.

Trademarks used are owned as indicated at fishersci.com/trademarks.

 **fisher scientific**  
part of Thermo Fisher Scientific