

FISHER SCIENTIFIC CLEANROOM ESSENTIALS

Are you concerned about contamination?

Do you want to be sure your transition areas are clean?

Ask us about our new range of tacky mats!

Tacky mats



Cat. No	Pack qty	Cat. No	Pack qty	Colour	Size, mm
30 layer mats		60 layer mats			
15301962	8	15331962	4	White	457 x 914
15361962	8	15391962	4	White	457 x 1143
15321972	8	15351972	4	White	610 x 914
13400329	8	15321982	4	White	660 x 1143
15371982	8	15301992	4	White	914 x 914
15351992	8	15381992	4	White	914 x 1143

Cat. No	Pack qty	Cat. No	Pack qty	Colour	Size, mm
30 layer mats		60 layer mats			
15381952	8	15311962	4	Blue	457 x 914
15341962	8	15371962	4	Blue	457 x 1143
15301972	8	15331972	4	Blue	610 x 914
13410329	8	15381972	4	Blue	660 x 1143
15351982	8	15381982	4	Blue	914 x 914
15321992	8	15361992	4	Blue	914 x 1143

Cat. No	Pack qty	Cat. No	Pack qty	Colour	Size, mm
30 layer mats		60 layer mats			
15391952	8	15321962	4	Grey	457 x 914
15351962	8	15381962	4	Grey	457 x 1143
15311972	8	15341972	4	Grey	610 x 914
15371972	8	15311982	4	Grey	660 x 1143
15361982	8	15391982	4	Grey	914 x 914
15341992	8	15371992	4	Grey	914 x 1143



Looking for quality cleanroom-specific paper and notebooks?

Using high quality cleanroom paper and notebooks helps reduce the risk of contamination



Cleanroom paper

Cat. No	Cat. No	Size	Weight, gsm	Colour	Pack qty
Innovative cleanroom paper for writing, printing and photocopying in cleanroom environments, available with either a synthetic or polyethylene substrate. Supplied in cases of 10 packs, each pack has 250 sheets. Case qty: 2500					
Synthetic		Polyethylene			
15773579	15793589	A4	80	White	10
15713579	15703589	A4	80	Blue	10
15793579		A4	80	Yellow	10
15743579		A4	80	Green	10

Cleanroom notebooks

Cat. No	Size	Colour	Pack qty
100 pages, latex-free paper. Impregnated and coated with a polymer formula that minimises fibre and particle generation			
15743609	A4	White	10
15773609	A5	White	20
15793609	A6	White	40

Looking for sterile pens with water resistant permanent ink?

See these sterile and individually bagged cleanroom marker pens

Cat. No	Colour	Pack qty
Processed in an NEBB certified ISO Class 4 cleanroom environment		
15994841	Black	10
15365905	Blue	10
15904851	Red	10



BioClean™

Looking for an affordable, quick and easy cleaning bucket system that can be readily stored in your cleanroom?

Ask us about the Mop Head Saturation System

Cat. No	Description	Dimensions, mm	Pack qty	
Production, assembling and packaging according to Cleanroom Class 7				
1	15964851	Compact Mop Head Saturation System, comprising two 8L stainless steel buckets, application frame & diffuser tray	510 x 300 x 250	1
	11942405	QuickConnect™ anodised aluminium telescopic handle	1300 to 2300	1
2	15895587	QuickTask™ hinged mop head frame	410 x 130	1
	15815597	Quiltec™ polyester mop head	390 x 130	40
	15817044	Quiltec™ sterile polyester mop head	390 x 130	40






CONTEC®



Are you struggling to clean your reusable samplers and remove all cross-contamination risks?

Try these sterile spoons, scoops and spatulas, individually packed. Production, assembly and packaging according to clean room class 7

Cat. No	Description	Capacity, mL	Length, mm	Pack qty	
Production, assembling and packaging according to Cleanroom Class 7					
2	15356327	Sterile spoon	2.5	127	100
	15351766	Sterile spoon	10	170	100
4	15614114	Sterile spoon-spatula	0.5	178	100
1	15624114	Sterile microspatula	1	180	100
3	15366317	Sterile scoop	25	141	10
	15386317	Sterile scoop	50	160	10
	15306327	Sterile scoop	100	205	10
	15316327	Sterile scoop	150	216	10
	15581721	Sterile scoop	250	250	10
	15501731	Sterile scoop	500	280	10
	15694104	Sterile scoop	1000	332	10

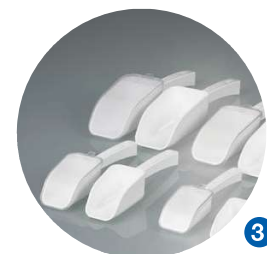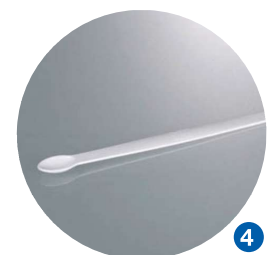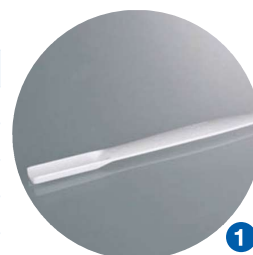

bürkle

Find out more at eu.fishersci.com

Austria: +43(0)800-20 88 40 Belgium: +32 (0)56 260 260 Denmark: +45 70 27 99 20
 Germany: +49 (0)2304 9325 Ireland: +353 (0)1 885 5854 Italy: +39 02 950 59 478
 Finland: +358 (0)9 8027 6280 France: +33 (0)3 88 67 14 14 Netherlands: +31 (0)20 487 70 00
 Norway: +47 22 95 59 59 Portugal: +351 21 425 33 50 Spain: +34 902 239 303
 Sweden: +46 31 352 32 00 Switzerland: +41 (0)56 618 41 11 UK: +44 (0)1509 555 500

© 2019 Thermo Fisher Scientific Inc. All rights reserved.
 Trademarks used are owned as indicated at fishersci.com/trademarks.

13666_EN

F fisher scientific
 part of Thermo Fisher Scientific